


Product Line Updates

The table below lists products that were featured in the previous catalog but not featured in this catalog. Customers are encouraged to choose the recommended substitutions. For details, or when a dash (–) is shown in the recommended substitutions, please contact the nearest Oriental Motor sales office.

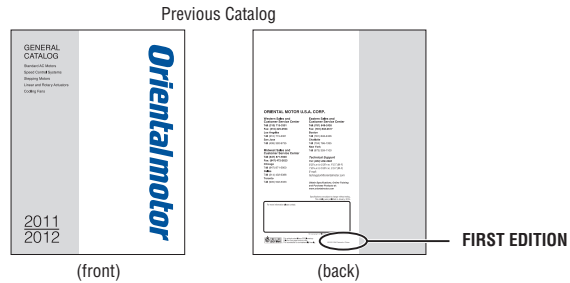

Brushless Motors (FBLII Series, Accessories)		
Previously Published Products	Recommended Substitutions	
Model	Model	Page
FBL575AW-□	BLE512A□S-3, BLE512A□S	D-89
FBL575CW-□	BLE512C□S-3, BLE512C□S	D-89
FBL575SW-□	BLE512S□S-3, BLE512S□S	D-89
FBL5120AW-□	BLE512A□S-3, BLE512A□S	D-89
FBL5120CW-□	BLE512C□S-3, BLE512C□S	D-89
FBL5120SW-□	BLE512S□S-3, BLE512S□S	D-89
FBL575AW-A	BLE512AA-3, BLE512AA	D-89
FBL575CW-A	BLE512CA-3, BLE512CA	D-89
FBL575SW-A	BLE512SA-3, BLE512SA	D-89
FBL5120AW-A	BLE512AA-3, BLE512AA	D-89
FBL5120CW-A	BLE512CA-3, BLE512CA	D-89
FBL5120SW-A	BLE512SA-3, BLE512SA	D-89
CC◇FBL	–	–
CC◇FBLR	–	–

- Enter the gear ratio in the box (□) within the model name.
- Enter the cable length in the box (◇) within the model name.
- The specifications and/or drawings of the recommended substitutions are different from those of the previously published products.
- For the dash (–) in the recommended substitutions, please contact the nearest Oriental Motor sales office.

Stepping Motors (AS Series Pulse Input, ASC Series, PK Series)		
Previously Published Products	Recommended Substitutions	
Model	Model	Page
AS46■A	AR46■A-3	A-32
AS66■AE	AR66■A-3	A-32
AS66■CE	AR66■C-3	A-32
AS66■SE	AR66■S-3	A-32
AS69■AE	AR69■A-3	A-32
AS69■CE	AR69■C-3	A-32
AS69■SE	AR69■S-3	A-32
AS98■AE	AR98■A-3	A-32
AS98■CE	AR98■C-3	A-32
AS98■SE	AR98■S-3	A-32
AS911AAE	AR911AA-3	A-32
AS911ACE	AR911AC-3	A-32
AS911ASE	AR911AS-3	A-32
AS66AAT	–	–
AS66ACT	–	–
AS66AST	–	–
AS69AAT	–	–
AS69ACT	–	–
AS69AST	–	–
AS98AAT	–	–
AS98ACT	–	–
AS98AST	–	–
AS911AAT	–	–
AS911ACT	–	–
AS911AST	–	–
AS46■A-T□	AR46■A-T□-3	A-33
AS66■AE-T□	AR66■A-T□-3	A-34
AS66■CE-T□	AR66■C-T□-3	A-34

Stepping Motors (AS Series Pulse Input, ASC Series, PK Series)		
Previously Published Products	Recommended Substitutions	
Model	Model	Page
AS66■SE-T□	AR66■S-T□-3	A-34
AS98■AE-T□	AR98■A-T□-3	A-35
AS98■CE-T□	AR98■C-T□-3	A-35
AS98■SE-T□	AR98■S-T□-3	A-35
AS46■A-N□	AR46■A-N□-3	A-39
AS66■AE-N□	AR66■A-N□-3	A-40
AS66■CE-N□	AR66■C-N□-3	A-40
AS66■SE-N□	AR66■S-N□-3	A-40
AS98■AE-N□	AR98■A-N□-3	A-41
AS98■CE-N□	AR98■C-N□-3	A-41
AS98■SE-N□	AR98■S-N□-3	A-41
AS46■A2-H□	AR46■A-H□-3	A-42
AS66■AE-H□	AR66■A-H□-3	A-42
AS66■CE-H□	AR66■C-H□-3	A-42
AS66■SE-H□	AR66■S-H□-3	A-42
AS98■AE-H□	AR98■A-H□-3	A-42
AS98■CE-H□	AR98■C-H□-3	A-42
AS98■SE-H□	AR98■S-H□-3	A-42
ASC34AK	AR24SAK-3	A-122
ASC36AK	AR26SAK-3	A-122
ASC46■K	AR46■K-3	A-122
ASC66■K	AR66■K-3	A-122
ASC34AK-T□	AR24SAK-T□-3	A-123
ASC46■K-T□	AR46■K-T□-3	A-124
ASC66■K-T□	AR66■K-T□-3	A-125
ASC34AK-N□	AR24SAK-N□-3	A-131
ASC46■K-N□	AR46■K-N□-3	A-132
ASC66■K-N□	AR66■K-N□-3	A-133
ASC34AK-H□	AR24SAK-H□-3	A-135
ASC46■K-H□	AR46■K-H□-3	A-135
ASC66■K-H□	AR66■K-H□-3	A-136
PK264-01AR◇	–	–
PK264-02AR◇	PK264-02AR◇	A-318
PK264-03AR◇	–	–
PK264-E2.0AR◇	–	–
PK266-01AR◇	–	–
PK266-02AR◇	PK266-02AR◇	A-318
PK266-03AR◇	–	–
PK266-E2.0AR◇	–	–
PK264M-01AR◇	–	–
PK264M-02AR◇	PK264MAR◇	A-298
PK264M-03AR◇	–	–
PK264M-E2.0AR◇	–	–
PK266M-01AR◇	–	–
PK266M-02AR◇	PK266MAR◇	A-298
PK266M-03AR◇	–	–
PK266M-E2.0AR◇	–	–

- Enter **A** (standard) or **M** (electromagnetic brake) in the box (■) within the model name.
- Enter the gear ratio in the box (□) within the model name.
- Enter the encoder code (**11** or **12**) in the box (◇) within the model name.
- Enter the encoder code (**15**, **16**, **25** or **26**) in the box (◇) within the model name.
- The specifications and/or drawings of the recommended substitutions are different from those of the previously published products.
- For the dash (–) in the recommended substitutions, please contact the nearest Oriental Motor sales office.

Motorized Cylinders (EZC Series, EZHC Series, EZHP Series, Accessories)		
Previously Published Products	Recommended Substitutions	
Model	Model	Page
EZC4-□CA	EZC4D□-K	E-62
EZC4-□CI	EZC4D□-K	E-62
EZC4-□MCA	EZC4D□M-K	E-62
EZC4-□MCI	EZC4D□M-K	E-62
EZC6-□CA	EZC6D□-K	E-66
EZC6-□CI	EZC6D□-K	E-66
EZC6-□MCA	EZC6D□M-K	E-66
EZC6-□MCI	EZC6D□M-K	E-66
EZHC4A-□A	EZA4D□-A	E-76
EZHC4A-□I	EZA4D□-A	E-76
EZHC4A-□MA	EZA4D□M-A	E-76
EZHC4A-□MI	EZA4D□M-A	E-76
EZHC6■-□A	EZA6D□-■	E-78
EZHC6■-□I	EZA6D□-■	E-78
EZHC6■-□MA	EZA6D□M-■	E-78
EZHC6■-□MI	EZA6D□M-■	E-78
EZHP4A-□A	EZA4E□-A	E-76
EZHP4A-□I	EZA4E□-A	E-76
EZHP4A-□MA	EZA4E□M-A	E-76
EZHP4A-□MI	EZA4E□M-A	E-76
EZHP6■-□A	EZA6E□-■	E-78
EZHP6■-□I	EZA6E□-■	E-78
EZHP6■-□MA	EZA6E□M-■	E-78
EZHP6■-□MI	EZA6E□M-■	E-78
CC◇EZ1	-	-
CC◇EZ1-M	-	-
CC◇EZ1-E	-	-
CC◇EZ1R	-	-
CC◇EZ1R-M	-	-
CC◇EZ1R-E	-	-
CC◇EZ2	-	-
CC◇EZ2-M	-	-
CC◇EZ2-E	-	-
CC◇EZ2R	-	-
CC◇EZ2R-M	-	-
CC◇EZ2R-E	-	-
CC02EZ1-S	-	-
CC002EZ1-L	-	-
CC002EZ2-L	-	-
PAEZ-BT	-	-
PAEZ-BT2	-	-
EZED1	-	-

- Enter the power supply voltage (A or C) in the box (■) within the model name.
- Enter the stroke length in the box (□) within the model name.
- Enter the cable length in the box (◇) within the model name.
- The specifications and/or drawings of the recommended substitutions are different from those of the previously published products.
- For the dash (-) in the recommended substitutions, please contact the nearest Oriental Motor sales office.

Safety Standards
Management of Chemical Substances in Products
ISO 9001, ISO 14001
Global Power Supply Voltages
Oriental Motor Corporate Overview
Oriental Motor Global Sales Network
Product Recommendation Information Sheets
Conversion Charts
Product Line Updates
Product Index